 
 





 KM size KM40 = 40 mm dia. KM50 = 50 mm dia. KM63 = 63 mm dia.	 Kennametal Capto size C4 = 40 mm dia. C5 = 50 mm dia. C6 = 63 mm dia.	 KMXMZ size KM63XMZ = 63 mm dia.	 		
1. System & Size			4. Hand of Tool	5. Blade Size	
KM40	KGM	S	R	50	
2. Kennametal Grooving Modular		3. Tool Style		6. Special Conditions	
				Y = Mazak Integrex Y-series machines	

(KM-KGMSR...)

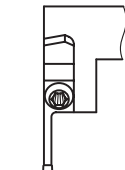

(KM-KGMEL...)

